

OncoPrint Precision Assay on Genexus NGS System

A next-generation solution for genomic profiling

Empower **your lab** to deliver NGS genomic profiles with the **speed** and **simplicity** of immunohistochemistry. Maximize your ability to deliver results even from small samples and low-level variants.

Minimum
sample
requirement



>95%
sample
success
rate

Maximum
results
obtained



Single-day
sample-to-report
workflow*

2 touch points
and only 10 min
of hands-on time




Curated pan-cancer content

- Mutations, CNVs, and fusion variant types across 50 key genes
- Tumor suppressors, drivers, and resistance variants



Tissue and plasma samples

- One test, one workflow, multiple sample types
- Maximizes the number of tumors that can be profiled

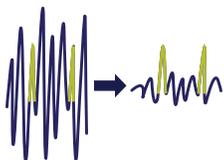

Molecular tagging

- Enhanced low-level variant detection
- Key for liquid biopsy testing



FusionSync™ Detection Technology

- Sensitive and specific—targeted isoform designs
- Novel fusion detection

* Specimen-to-report workflow will be available after the Genexus Purification System and integrated reporting capabilities are added in 2020.

Find out more at oncoPrint.com/genexus-oncology

Contact us today:

In the United States

Order online: fishersci.com

Fax an order: 1-800-926-1166

Call customer service: 1-800-766-7000

 **fisher scientific**
part of Thermo Fisher Scientific

© 2020 Thermo Fisher Scientific Inc. All rights reserved.

Trademarks used are owned as indicated at fishersci.com/trademarks.

For Research Use Only. Not for use in diagnostic procedures. ©2019 Thermo Fisher Scientific Inc. All rights reserved. All trademarks are the property of Thermo Fisher Scientific and its subsidiaries unless otherwise specified. The content provided herein may relate to products that have not been officially released and is subject to change without notice.

COL010594 1019