

Labconco® Glassware Washers



Both washers are designed to wash and dry a variety of general purpose labware with the SteamScrubber better suited for wide-mouth and the FlaskScrubber accommodating narrow-neck glassware.

All models feature:

Materials/Construction

- 304 stainless steel top, door, tank, upper and lower wash arms. Freestanding models also have stainless steel exterior sides and top
- One piece, tool-free, stainless steel, mesh sump filter
- Four leveling feet
- Aluminum-backed insulation and fiberglass thermal blanket
- Factory-installed drain hose and band clamp
- Two year warranty on parts and labor

Performance

- Water temperature up to 93° C (199°F)
- Pump rated at 96 gal/min (363 L/min) when operated at 115V, 60 Hz and 208/230V, 50 Hz and 112 gal/min (424 L/min) on 208/230V, 60 Hz
- Synchronous drain pump rated at up to 4.2 gal/min (16 L/min)

- Purified water pump
- Forced air drying into the tank programmable up to 240 minutes and from 25-80° C (77-176° F)
- Electronic door latch with SpeedVent Technology
- Detergent dispenser for powder or liquid detergent
- Level-sensing 6 ml rinse aid solution dispenser
- Operation at or below 62 decibels

Controls/User Interface

- Full color touch screen display with CleanWorks™ OS
- 9 factory-set programs: Up to 200-user defined programs
- Clear and specific alarm displays
- Robust diagnostic menu
- Password protection
- User configurable delayed start (up to 12 hours)
- USB data output

Options include:

- Freestanding and undercounter styles
- Clear tempered safety glass viewing window and 25-watt LED interior
- Single-phase (1.2 kW, 2kW) or three-phase (6 kW) electrical

Description	Electrical Requirements	Overall Dimensions (w x d x h)	Interior Dimensions (w x d x h)	Shipping Weight	Cat. No
FlaskScrubber	115 V, 60 Hz, 16 A, 1P	24.1x27.7x32.1-36	24.2x27.7x32.1-36	202 lbs.	41-100-1000
FlaskScrubber	115 V, 60 Hz, 16 A, 1P	24.3x27.8x32.2-36.2	24.3x27.8x32.2-36.2	230 lbs.	41-200-1000
SteamScrubber	115 V, 50/60 Hz, 16 A, 1P	24.1x27.7x32.1-36	24.2x27.7x32.1-36	202 lbs.	40-100-1000
SteamScrubber	115 V, 50/60 Hz, 16 A, 1P	24.3x27.7x32.2-36.2	24.3x27.8x32.2-36.2	230 lbs.	40-200-1000

Optional Accessories



Holder, Glassware Glassware Holder for FlaskScrubber and SteamScrubber Glassware Washers. 3.9 in. h .4 lbs., **10359090**




15352808E




352808D

Holder, Glassware 4", 6" Vinyl-coated. Type 304 stainless steel wire with height adjustment screw. Fit onto spindles to grip glassware and hold it in place. 4 in. h 4 lbs. 15352808D, 6 in. h, .4 lbs. **15352808E**

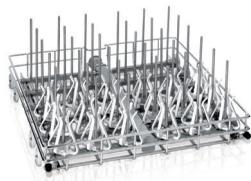

Lower Spindle Rack with Carton Designed for cleaning narrow-neck labware. Includes 36 spindles, 36 adjustable height clips, 18 glassware holders, 10 small spindles and clips, 36 spindle plugs, and 12 spindle arm plugs. 21.4x20.9x8.6, 21 lbs. **15352038**

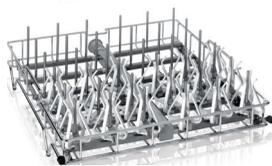

Upper Spindle Rack with Slides Designed for cleaning narrow-neck labware. Includes 36 spindles, 36 adjustable height clips, 18 glassware holders, 10 small spindles and clips, 36 spindle plugs, and 12 spindle arm plugs. 21.6x20.8x6.9, 23 lbs., **15352034**




Upper Standard Rack with Slides Upper Standard Rack is open to accommodate accessory inserts to suit your labware needs (inserts sold separately). Constructed of type 304 stainless steel. Includes wash arm and upper slide rails. 21.5x20.8x6, 20 lbs., **15352036**



Utensil Basket Packaged For miscellaneous labware such as stoppers, spatulas and other small lightweight items. Type 304 stainless steel. For use in Labconco Upper or Lower, Standard or Spindle Rack. 8.9x8.9x4, 3 lbs., **15-352-001**



Utensil Holder Packaged For spatulas, spoons, scoops and other miscellaneous utensils. Utensils fit into 6 spacious compartments. For use in Labconco Upper or Lower Standard or Spindle Rack. 8.2x8.2x8, 5 lbs., **15-352-014**

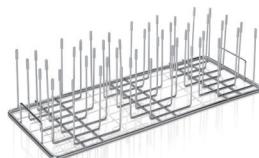

48-Pin Insert Securely holds smaller volume wide-mouth labware. Type 304 stainless steel with silicone tips to prevent scratching. For use in Labconco Upper or Lower, Standard or Spindle Rack. 10-Pin and 32-Pin Inserts also available. 8.5x18.5x4.5, 5 lbs., **15-352-008**

Find out more at fishersci.com Search: Labconco washers

Distributed by Fisher Scientific. Contact us today:

In the United States

Order online: fishersci.com
Call customer service: 1-800-766-7000

In Canada

Order online: fishersci.ca
Call customer service: 1-800-234-7437

